

外装パーツ

Webなら盤用パーツ多数掲載!

ミスミ

ゴム足



ココが特長 サイズ・耐荷重のバリエーションが豊富です
●RoHS対応済みのゴム足

在庫品

RoHS



Order
注文例

型番 - No.
C-30-RK - 18




1個単位

型番	No.	H1	H2	D1	D2	d1	d2	推奨取付 ネジサイズ	荷重 (kg)	たわみ (mm)	製品自重 (g)	¥通常単価			¥スライド単価		
												1~19個	20~39個	40~99個	1~19個	20~39個	40~99個
C-30-RK	10	5	3	10	10	3	5	M3	10	1	0.5	110	60	44			
	12	9	4	12	8	3	5	M3	6	2	1	110	60	44			
	15	8	5	15	14	3	6	M3	15	2	2	110	60	44			
	1510	10	3	15	10	3	5	M3	11	2	2	110	60	44			
	16	10	5	16	14	3	6	M3	15	2	3	110	60	44			
	18	11	7	18	15	4	7	M4	15	2	4	120	70	48			
	20	12	7	20	16	4	7	M4	20	2.5	5	120	70	48			
	2017	17	8	20	15	3	7	M3	10	1	6	120	70	48			
	22	24	10	22	18	3	7	M3	10	1	12	140	90	56			
	23	14	5	23	19	4	8	M4	25	2.3	8	120	70	48			
	2320	20	10	23	20	4	8	M4	10	1	11	130	80	52			
	24	10	5	24	19	4	9	M4	20	2	6	120	70	48			
	26	15	10	26	20	4	10	M4	30	3	10	130	80	52			
	28	18	11	28	22	4	12	M4	30	4	12	130	80	52			
	29	15	10	29	24	4	14	M4	30	3	12	140	90	56			
	30	19	10	30	24	4	14	M4	30	3.5	15	140	90	56			
	3215	15	5	32	26	5	14	M5	45	2.4	15	140	90	56			
	3220	20	10	32	26	5	15	M5	50	2.3	20	140	90	56			
	3225	25	9	32	28	5	14	M5	50	4.3	28	160	110	64			
	34	18	10	34	26	5	17	M5	40	4	18	150	100	60			
3617	17	9	36	20	6	17	M6	15	1	21	160	110	64				
36	22	12	36	30	5	12	M5	60	3.5	28	160	110	64				
38	24	13	38	32	5	12	M5	100	4	35	180	130	76				
40	22	9	40	28	5	14	M5	70	3	30	170	120	66				
45	27	12	45	35	5	12	M5	100	3	52	270	220	171				
63	26	15	63	48	7	14	M6	40	1	103	375	325	237				


外形図

(単位: mm)

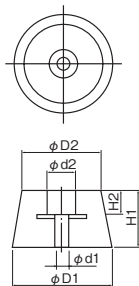

ご注意

C-30-RK-10、C-30-RK-3617は、
下図のような形状になります。

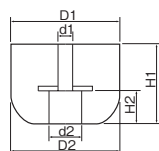

材質: EPDM(黒色)
硬度: 65 \pm 5, 使用温度 \sim 70 $^{\circ}$ C